


MNX ABS 175/100 HT

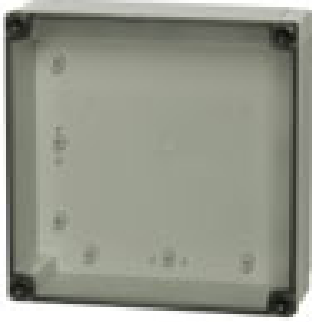

Sample photo

Order symbol: ABS 175/100 HT
Product nbr: 6081921
Description: Enclosure, ABS
Remarks: Smoked transparent cover

EAN: 6418074023223
EI. number:
 Finland: 3420643
 Electric No. Denmark: 8212023615
 Electric No. Italy: 7362115
 Electric No. Sweden: 2535866

Including: Base with TPE gasket, screws for mounting plate/DIN-rail and cover with polyamide cover screws.

Dimensions: Length Width Height **Accessories:**

mm:	180	180	100
inch:	7.1	7.1	3.9

MIN 15	DIN-15 Mounting rail
MIV 15	DIN-35 Mounting rail
FP A 175/180	Front plate (Aluminium)
HFP 180	Front plate hinge series
FP 22046	Wall fastening lug (4 pcs)

Materials:

Material:	ABS
Base colour:	RAL 7035 -light grey
Cover screws material:	Polyamide
Cover colour:	Smoked grey
Cover screws colour:	Black
Gasket material:	TPE

Rating:

Ingress Protection (EN 60529): IP66/IP67
 Impact Resistance (EN 62262): IK07
 Electrical insulation: Totally insulated
 Halogen free (DIN/VDE 0472, Part 815): 1
 Flammability Rating: UL 94 HB
 Glow Wire Test (IEC 695-2-1) °C: 650
 NEMA Class: NEMA 1, 4, 4X, 6, 12, 13

Temperatures:

Temperature °C (short term):	-40 ... 80 °C
Temperature °C (continuous):	-40 ... 60 °C
Temperature °F (short term):	-40 ... 175 °F
Temperature °F (continuous):	-40 ... 140 °F

Certificates:

SGS Fimko
 Gost R

Accessories:

MIV 175 Mounting plate (Galvanized steel)

